


HITRONIC® HQA

가 ; ADSS

HITRONIC® HQA ADSS (), ,

A-DQ(ZN)2Y

ADSS - All Dielectric Self Supporting

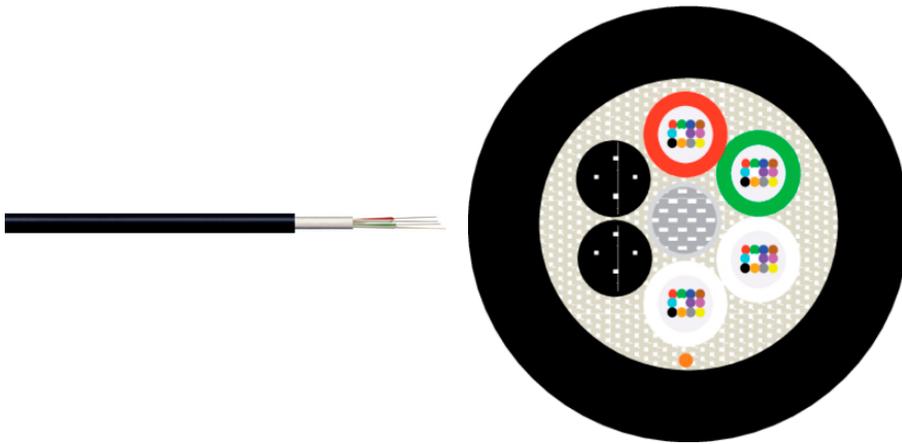

, ,
()

(03.05.2024)

HITRONIC® HQA

가 96
()
90m

GRP 8
(Aramid Yarns)
PE : (RAL 9005)

ETIM 5: ETIM 5.0 Class-ID: EC000034
ETIM 5.0 Class-Description:
ETIM 6: ETIM 6.0 Class-ID: EC000034
ETIM 6.0 Class : LWL
: 1 : 250µm
:

Fibre type: GOF - Glass Optical Fibre
:: A-DQ(ZN)2Y - ADSS
: All-Dielectric Self-Supporting
:
: :
가 : : 15 x
: 20 x
가 : MAT: 2000 N
EDS: 800 N
: : -40°C ~ +70°C
: -30 °C ~ +70 °C

가 VAT 가 가 . 가 가 . (.) 가 .
가



HITRONIC® HQA

		Fibre type	Number of fibres	(mm)	(kg/km)
E 9 OS2					
26640912	HITRONIC® HQA800 6x2E 9/125 OS2	9/125 OS2	12	9.7	73
26640924	HITRONIC® HQA800 6x4E 9/125 OS2	9/125 OS2	24	9.7	73
26640948	HITRONIC® HQA800 6x8E 9/125 OS2	9/125 OS2	48	10.9	92
26640996	HITRONIC® HQA800 8x12E 9/125 OS2	9/125 OS2	96	12.4	121

(03.05.2024)

©2024 Lapp Group - all rights reserved.

<http://lappkorea.lappgroup.com>

data sheet

PN 0456 / 02_03.16