

# ÖLFLEX® HEAT 125 MC 300/500 V


가

가

ÖLFLEX® HEAT 125 MC - halogen free power and control cable with DNV GL certificate, special fire performance, IEC 60332-3, suitable for +125°C

CPR: [www.lappkabel.com/cpr](http://www.lappkabel.com/cpr)

DNV GL approved

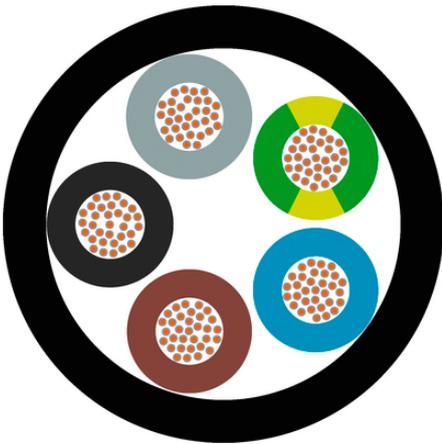

(08.05.2024)





# ÖLFLEX® HEAT 125 MC 300/500 V

가 가 . ( . ) 가 .  
: [www.lappkabel.de/en/cable-standradlengths](http://www.lappkabel.de/en/cable-standradlengths)  
30 kg or 250 m,  
(e.g. 1 x 500 m or 5 x 100 m ).  
가 VAT 가 가 .



# ÖLFLEX® HEAT 125 MC 300/500 V

	(CORE) / (mm <sup>2</sup> )	(mm)	(kg/km)	(kg/km)
ÖLFLEX® HEAT 125 MC 300/500 V				
1024300	2 X 0.5	6.0	9.6	38
1024301	3 G 0.5	6.3	14.4	46
1024360	3 X 0.5	6.3	14.4	60.37
1024302	4 G 0.5	6.9	19.2	55
1024361	4 X 0.5	6.9	19.2	72.74
1024303	5 G 0.5	7.5	24	86.45
1024304	7 G 0.5	8.4	33.6	109.7
1024307	2 X 0.75	6.4	14.4	40
1024308	3 G 0.75	6.8	21.6	53
1024362	3 X 0.75	6.8	21.6	72.34
1024309	4 G 0.75	7.4	28.8	69
1024363	4 X 0.75	7.4	28.8	87.55
1024310	5 G 0.75	8.3	36	86
1024311	7 G 0.75	9.0	50	127
1024312	12 G 0.75	12.2	86	218.69
1024315	2 X 1.0	6.6	19.2	50
1024316	3 G 1.0	7.0	28.8	67
1024364	3 X 1.0	7.0	28.8	80.74
1024317	4 G 1.0	7.8	38.4	87
1024365	4 X 1.0	7.8	38.4	102.13
1024318	5 G 1.0	8.6	48	107
1024319	7 G 1.0	9.5	67	152
1024320	12 G 1.0	12.8	115	221

(08.05.2024)

©2024 Lapp Group - all rights reserved.

<http://lappkorea.lappgroup.com>

data sheet

PN 0456 / 02\_03\_16