


ÖLFLEX® SERVO Core Line for Siemens 6FX8002 (PUR)

가

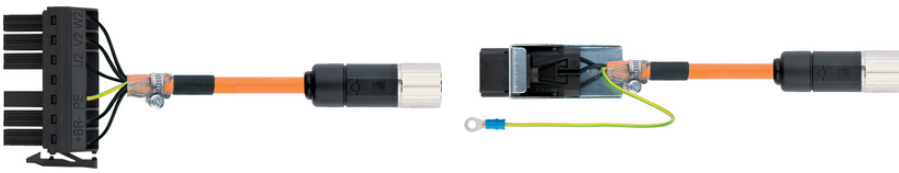

Lapp



가

Lapp

(24.04.2024)

©2024 Lapp Group - all rights reserved.

<http://lappkorea.lappgroup.com>

data sheet

PN 0456 / 02_03.16



ÖLFLEX® SERVO Core Line for Siemens 6FX8002 (PUR)

For travel distances up to 10 m

PUR

SIEMENS®

1.5 mm²

가

ETIM 5:

ETIM 5.0 Class-ID: EC000104
ETIM 5.0

:

U/L2/C/L +

: V / L2

:

: W/L3/D/L-GN/YE

: WS; SW

:

IEC 60228/VDE 0295 class 5

:

Chain application: 7,5 x cable diameter
: 4 x

:

U0/U: 600/1000 V
UL & CSA: 1000 V

:

Core/Core: 4 kV
Core/Screen: 4 kV

:

G = GN/YE

:

: -40 ~ 90°C(UL/CSA: 80°C)
: -50 ~ 90°C(UL/CSA: 80°C)

:

5 mio. cycles

Siemens

(6FX5002/5008, 6FX7002/7008, 6FX8002/8008) Siemens AG

가

가 VAT

가 가

Further Article and length online <https://servoconfigurator.lappgroup.com/>

(24.04.2024)



ÖLFLEX® SERVO Core Line for Siemens 6FX8002 (PUR)

	(mm)	(m)	(CORE) / (mm ²)	SIEMENS®	kg/1.000 pieces		PU
ÖLFLEX® SERVO Core Line for Siemens 6FX8002 (PUR)							
5480005390	11.5	10.0	4 G 2,5	5CS31	1290	가	1
5480000665	10	10.0	4 G 1,5	5CN01	738.4	가	1
5480000715	11.5	10.0	4 G 2,5	5CN11	1230	가	1
5480000765	11.5	10.0	4 G 2,5	5CN31	1230	가	1
5480001065	10	10.0	4 G 1,5	5CS01	738.4	가	1
5480001115	11.5	10.0	4 G 2,5	5CS11	1230	가	1
5480001215	10	10.0	4 G 1,5	5CS21	830.25	가	1
5480001765	14.4	10.0	4 G 2,5+(2x1,5)	5DN11	2,078.7	가	1
5480001840	16.3	10.0	4 G 4,0+(2x1,5)	5DN41	2,769.55	가	1
5480002115	12.8	10.0	4 G 1,5+(2x1,5)	5DS01	1,365.4	가	1
5480049200	10	10.0	4 G 1,5	5CS06	1,365.4	가	1
5480002215	14.4	10.0	4 G 2,5+(2x1,5)	5DS31	2028	가	1

(24.04.2024)

©2024 Lapp Group - all rights reserved.

<http://lappkorea.lappgroup.com>

data sheet

PN 0456 / 02_03.16