


ÖLFLEX® CLASSIC 128 H BK SC

Cost-effective halogen-free single core power cable with improved fire characteristics, 0,6/1kV

ÖLFLEX® CLASSIC 128 H BK SC, Single core power cable, halogen-free, highly flame retardant, HFFR, flexible, conductor class 5, public buildings

CPR: www.lappkabel.com/cpr

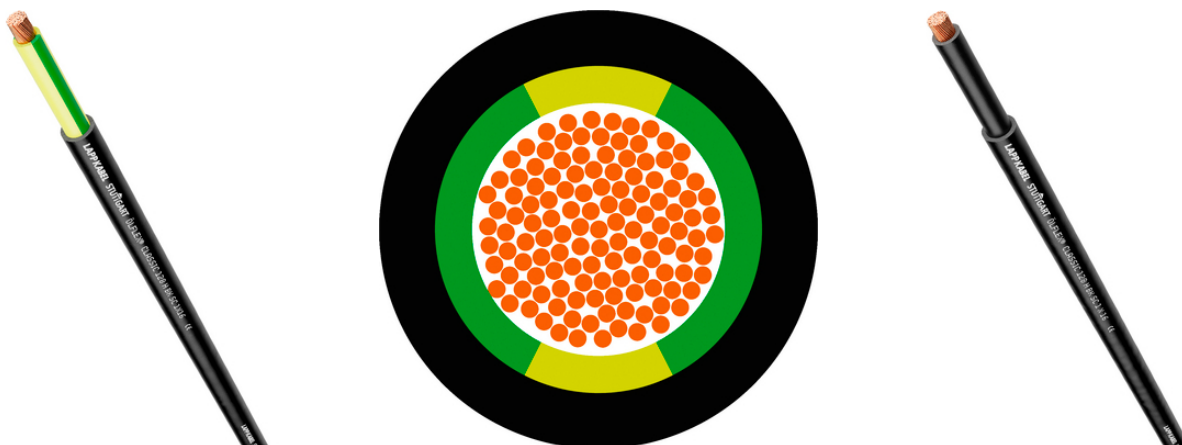

Easy handling and installation due to flexible design
(CPR)

T14

Halogen-free and highly flame-retardant materials reduce the risk of fire propagation, high smoke density and toxic fumes in case of fire

(22.02.2024)

©2024 Lapp Group - all rights reserved.

<http://lappkorea.lappgroup.com>

data sheet

PN 0456 / 02_03.16



ÖLFLEX® CLASSIC 128 H BK SC

가 VAT 가 가 .

(22.02.2024)

©2024 Lapp Group - all rights reserved.

<http://lappkorea.lappgroup.com>


data sheet

PN 0456 / 02_03.16

ÖLFLEX® CLASSIC 128 H BK SC

Article number	(CORE) / (mm ²)	(mm)		(kg/km)	(kg/km)
1123800	1 X 16.0	9.6		153.6	219
1123811	1 G 16.0	9.6	-	153.6	219
1123801	1 X 25.0	11.3		240	327
1123812	1 G 25.0	11.3	-	240	327
1123802	1 X 35.0	12.5		336	436
1123813	1 G 35.0	12.5	-	336	436
1123803	1 X 50.0	15.1		480	587
1123814	1 G 50.0	15.1	-	480	587
1123804	1 X 70.0	17.0		672	798
1123815	1 G 70.0	17.0	-	672	798
1123805	1 X 95.0	19.6		912	1044
1123816	1 G 95.0	19.6	-	912	1044
1123806	1 X 120.0	22.4		1152	1339
1123817	1 G 120.0	22.4	-	1152	1339
1123807	1 X 150.0	24.2		1440	1633
1123818	1 G 150.0	24.2	-	1440	1633
1123808	1 X 185.0	26.3		1776	1943
1123819	1 G 185.0	26.3	-	1776	1943
1123809	1 X 240.0	30.8		2304	2597
1123820	1 G 240.0	30.8	-	2304	2597

ÖLFLEX® CLASSIC 128 H BK SC

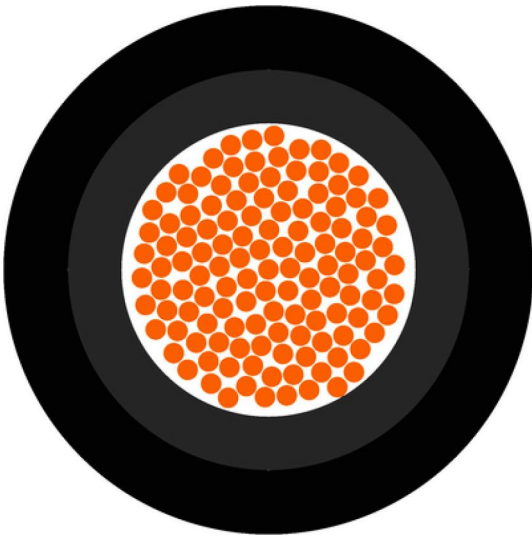

(22.02.2024)

©2024 Lapp Group - all rights reserved.

<http://lappkorea.lappgroup.com>

data sheet

PN 0456 / 02_03.16