


SILVYN® US-M

SILVYN® US-M

IP40/IP54/IP66

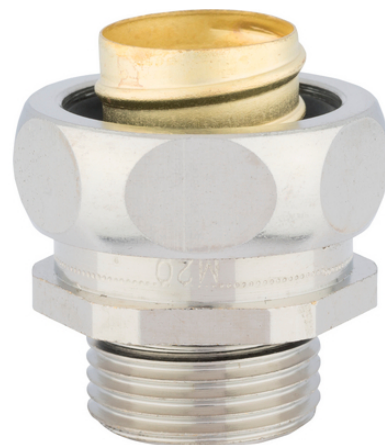

**CE UK
CA**



SILVYN®

AS/AS-P/EDU-AS/EMC AS-CU

(24.04.2024)

©2024 Lapp Group - all rights reserved.

<http://lappkorea.lappgroup.com>

data sheet

PN 0456 / 02_03.16

SILVYN® US-M

6

PG threaded versions are to be found in the online catalogue

ETIM 5:

ETIM 5.0 Class-ID: EC001180

ETIM 5.0 Class :

ETIM 6:

ETIM 6.0 Class-ID: EC001180

ETIM 6.0 Class :

:

:

: TPE

가:

IP 40 (SILVYN® AS, EDU-AS EMC AS-CU)

IP 54 (SILVYN® FPS FD-PU)

IP 66 (SILVYN® AS-P)

:

-40°C +125°C

가 VAT 가 가 .

(24.04.2024)

©2024 Lapp Group - all rights reserved.

<http://lappkorea.lappgroup.com>

data sheet

PN 0456 / 02_03.16

SILVYN® US-M

		(mm)		/ PU
SILVYN® US-M for SILVYN® AS				
55502611	10 x 1.0	6.5	10	50
55502612	12 x 1.5	9	14	50
55502613	16 x 1.5	12.5	17	50
55502614	20 x 1.5	16	21	50
55502615	25 x 1.5	21	27	25
55502616	32 x 1.5	27.5	36	25
55502617	40 x 1.5	35	45	20
55502618	50 x 1.5	45	56	10
55502619	63 x 1.5	45	56	10
SILVYN® US-M for SILVYN® AS-P				
55502621	10 x 1.0	6	10	50
55502622	12 x 1.5	8.5	14	50
55502623	16 x 1.5	11.5	17	50
55502624	20 x 1.5	15.5	21	50
55502625	25 x 1.5	20.5	27	25
55502626	32 x 1.5	27.5	36	25
55502627	40 x 1.5	35	45	20
55502628	50 x 1.5	45	56	10
55502629	63 x 1.5	45	56	10
SILVYN® US-M for SILVYN® EDU-AS / EMC AS-CU				
55502631	10 x 1.0	6	10	50
55502642	12 x 1.5	8.5	14	50
55502633	16 x 1.5	11	17	50
55502634	20 x 1.5	15.5	21	50
55502636	25 x 1.5	20.5	27	25
55502646	32 x 1.5	27.5	36	25
55502638	40 x 1.5	35	45	20
55502639	50 x 1.5	45	56	10
55502641	63 x 1.5	45	56	10

SILVYN® US-M



(24.04.2024)

©2024 Lapp Group - all rights reserved.

<http://lappkorea.lappgroup.com>

data sheet

PN 0456 / 02_03.16