


® UI 511

SILVYN® UI

- SILVYN® UI 511

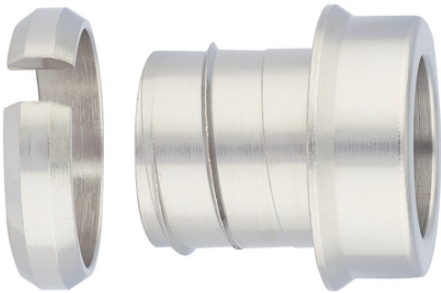

SILVYN® UI 511 :

ETIM 5:

ETIM 5.0 Class-ID: EC000519

ETIM 5.0 Class :

ETIM 6:

ETIM 6.0 Class-ID: EC000519

ETIM 6.0 Class :

:

:

-55 °C +260 °C

(20.07.2024)

©2024 Lapp Group - all rights reserved.

<http://lappkorea.lappgroup.com>

data sheet

PN 0456 / 02\_03.16



® UI 511

가 VAT 가 가 .

(20.07.2024)



® UI 511

	( )	SILVYN® UI 511	/ PU
61798091	5/16"	5/16"	10
61798096	3/8"	3/8"	10
61798097	1/2"	1/2"	10
61798092	3/4"	3/4"	5
61798093	1"	1"	5
61798094	1 1/4"	1 1/4"	2
61798090	1 1/2"	1 1/2"	2
61798095	2"	2"	2

(20.07.2024)

©2024 Lapp Group - all rights reserved.

<http://lappkorea.lappgroup.com>

data sheet

PN 0456 / 02\_03.16