


# SILVYN® FPAS

SILVYN® FPAS

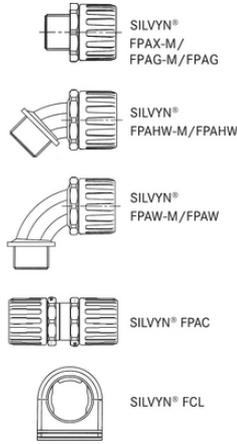

, UL 94V-2

/

(23.04.2024)



# SILVYN® FPAS

, ,

UL FILENUMBER E308201

6

ETIM 5:

ETIM 5.0 Class-ID: EC001175  
ETIM 5.0 Class :

ETIM 6:

ETIM 6.0 Class-ID: EC001175  
ETIM 6.0 Class :

:

IEC EN 61386-23

:

PA 12 가

:

(RAL 7031)  
(RAL 9005), UV

:

PA 6

:

UL94 V-2

-40°C ~ +120°C  
-20°C ~ +100°C

가 VAT 가 가 .

(23.04.2024)



SILVYN® FPAS

	( )	ID x OD mm	(mm)	PU ring (m)
SILVYN® FPAS				
61754005	10	6.3 x 10	15	50
61754015	13	9.8 x 13	25	50
61754025	16	11.8 x 15.8	35	50
61754275	18	14.2 x 18.5	40	50
61737162	20	14.8 x 20	45	50
61754035	21	16.7 x 21.2	45	50
61737164	25	19.1 x 25	50	50
61754045	28	22.8 x 28.5	50	50
61754055	34	28.1 x 34.5	60	25
61754065	42	35.5 x 42.5	70	25
61754075	54	47.2 x 54.5	80	25
61754305	67	56.3 x 67.2	130	10
61737246	10	6.3 x 10.0	15	10
61737247	13	9.8 x 13.0	25	10
61737248	16	11.8 x 15.8	35	10
61737252	18	14.2 x 18.5	40	10
61737249	21	16.7 x 21.2	45	10
61737250	28	22.8 x 28.5	50	10
61737251	34	28.1 x 34.5	60	10
SILVYN® FPAS				
61754000	10	6.3 x 10	15	50
61754010	13	9.8 x 13	25	50
61754020	16	11.8 x 15.8	35	50
61754270	18	14.2 x 18.5	40	50
61737253	20	14.8 x 20	45	50
61754030	21	16.7 x 21.2	45	50
61737163	25	19.1 x 25	50	50
61754040	28	22.8 x 28.5	50	50
61754050	34	28.1 x 34.5	60	25
61754060	42	35.5 x 42.5	70	25
61754070	54	47.2 x 54.5	80	25
61754300	67	56.3 x 67.2	130	10

(23.04.2024)

©2024 Lapp Group - all rights reserved.

<http://lappkorea.lappgroup.com>

data sheet

PN 0456 / 02\_03\_16