

## SILVYN® ELÖ

SILVYN® ELÖ - PVC



ASTM2

가

SILVYN® MPC / MPC-M

(28.02.2024)

©2024 Lapp Group - all rights reserved.

<http://lappkorea.lappgroup.com>

data sheet

PN 0456 / 02\_03.16



# SILVYN® ELÖ

UL FILENUMBER E308201

PVC  
PVC

UL

ETIM 5:

ETIM 5.0 Class-ID: EC001177

ETIM 5.0 Class :

ETIM 6:

ETIM 6.0 Class-ID: EC001177

ETIM 6.0 Class :

:

IEC EN 61386-23

:

(RAL 6001)

:

PVC 가 PVC

:

-20°C ~ +70°C

가 VAT 가 가 .

(28.02.2024)

©2024 Lapp Group - all rights reserved.

<http://lappkorea.lappgroup.com>

data sheet

PN 0456 / 02\_03.16

# SILVYN® ELÖ

|             | ( ) | ID x OD mm  | (mm) | SILVYN® MPC-<br>M/MPC 90°M | SILVYN® MPC | SILVYN® MPC 90° | PU (m) |
|-------------|-----|-------------|------|----------------------------|-------------|-----------------|--------|
| SILVYN® ELÖ |     |             |      |                            |             |                 |        |
| 61751610    | 12  | 10 x 14.5   | 25   | 16/1                       | 9           | 9               | 30     |
| 61751620    | 16  | 12 x 16.5   | 25   | 16/2 , 20/1                | 11 , 13,5/1 | 11 , 13,5/1     | 30     |
| 61751630    | 20  | 16 x 21     | 35   | 20/2                       | 13,5/2 , 16 | 13,5/2 , 16     | 30     |
| 61751640    | 25  | 22 x 27.5   | 45   | 25 x 1,5                   | 21          | 21              | 30     |
| 61751650    | 30  | 25 x 30.5   | 55   | 32/1                       | 21          | 21              | 30     |
| 61751660    | 32  | 28 x 33.5   | 60   | 32/2                       | 29/2        | 29/2            | 30     |
| 61751670    | 40  | 35 x 41     | 80   | 40 x 1,5                   | 36          | 36              | 30     |
| 61751680    | 50  | 40 x 46.4   | 105  | 50 x 1,5                   | 42          | -               | 30     |
| 61751690    | 63  | 50 x 57     | 120  | 63 x 1,5                   | 48          | -               | 30     |
| 61737290    | 12  | 10.0 x 14.5 | 25   | 16/1                       | 9           | 9               | 10     |
| 61737291    | 16  | 12.0 x 16.5 | 25   | 16/2 , 20/1                | 11 , 13,5/1 | 11 , 13,5/1     | 10     |
| 61737292    | 20  | 16.0 x 21.0 | 35   | 20/2                       | 13,5/2 , 16 | 13,5/2 , 16     | 10     |
| 61737293    | 25  | 22.0 x 27.5 | 45   | 25 x 1,5                   | 21          | 21              | 10     |
| 61737294    | 30  | 25.0 x 30.5 | 55   | 32/1                       | 21          | 21              | 10     |
| 61737295    | 32  | 28.0 x 33.5 | 60   | 32/2                       | 29/2        | 29/2            | 10     |
| 61737296    | 40  | 35.0 x 41.0 | 80   | 40 x 1,5                   | 36          | 36              | 10     |
| SILVYN® ELÖ |     |             |      |                            |             |                 |        |
| 61751611    | 12  | 10 x 14.2   | 50   | -                          | -           | -               | 30     |
| 61751621    | 16  | 12 x 17.8   | 50   | 16/2 , 20/1                | 11 , 13,5/1 | 11 , 13,5/1     | 30     |
| 61751631    | 20  | 16 x 21.1   | 70   | 20/2                       | 13,5/2 , 16 | 13,5/2 , 16     | 30     |
| 61751641    | 25  | 21 x 26.4   | 90   | 25x1,5                     | 21          | 21              | 30     |
| 61751661    | 32  | 26.5 x 33.1 | 140  | 32/2                       | 29/2        | 29/2            | 30     |
| 61751671    | 40  | 35.4 x 41.8 | 190  | 40 x 1,5                   | 36          | 36              | 30     |
| 61751681    | 50  | 40 x 47.9   | 240  | 50 x 1,5                   | 42          | -               | 30     |
| 61751691    | 63  | 51.3 x 59.7 | 270  | 63 x 1,5                   | 48          | -               | 30     |

(28.02.2024)



©2024 Lapp Group - all rights reserved.

<http://lappkorea.lappgroup.com>

data sheet

PN 0456 / 02\_03.16

## SILVYN® ELÖ

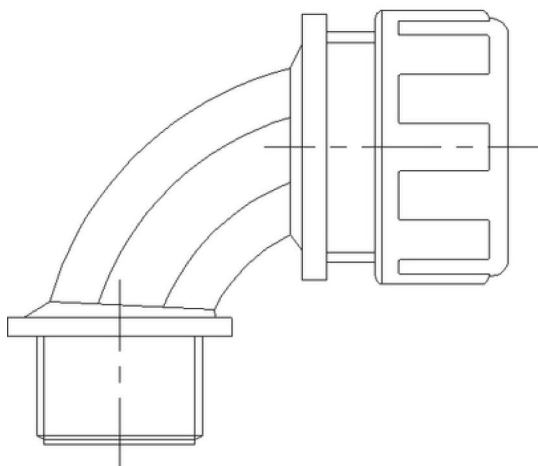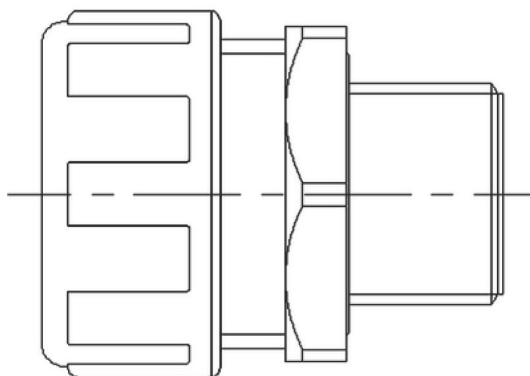

(28.02.2024)

©2024 Lapp Group - all rights reserved.

<http://lappkorea.lappgroup.com>

data sheet

PN 0456 / 02\_03.16