


SILVYN® SSV-M

SILVYN® SSV-M -

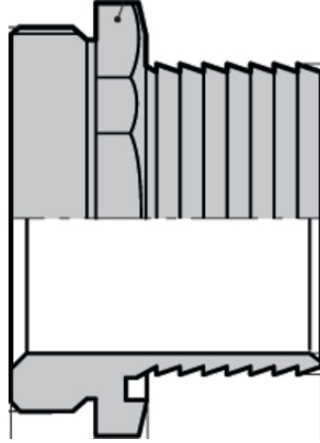

가

SILVYN® SI

SILVYN® SP

SILVYN® SP-PU

SILVYN® SCH

(12.05.2024)



SILVYN® SSV-M

PG threaded versions are to be found in the online catalogue

ETIM 5:	ETIM 5.0 Class-ID: EC001180
	ETIM 5.0 Class :
ETIM 6:	ETIM 6.0 Class-ID: EC001180
	ETIM 6.0 Class :
:	:
	O- : NBR
:	-20°C +80°C

가 VAT 가 가 .



SILVYN® SSV-M

		SW (mm)	mm	(thread) (mm)	(mm)	SILVYN® SCH	SILVYN® SI	SILVYN® SP	SILVYN® SP- PU	/ PU
SILVYN® SSV-M										
52002827	12 x 1.5/1	16	25	8	7	10 - 16 S	7 x 9	-	-	50
52002828	12 x 1.5/2	19	25	8	9	10 - 16 S	9 x 12	-	-	50
52002840	16 x 1.5/1	19	25	8	8	10 - 16 S	11 x 14	10 x 14	10 x 14	50
52002839	16 x 1.5/2	19	25	8	10	12 - 20 S	13 x 16	12 x 16	12 x 16	50
52002841	20 x 1.5/1	22	25	8	12	16 - 25 S	14 x 18	-	-	50
52002842	20 x 1.5/3	25	25	8	15.5	20 - 32 S	18 x 22	-	-	50
52002843	25x1.5	32	29.5	8.5	19	20 - 32 S	23 x 28	22 x 27	22 x 27	25
52002844	32 x 1.5	40	32.5	9.5	27	25 - 40 S	32 x 38	30 x 36	30 x 36	25
52002845	40x1.5	50	36	11	34	35 - 50 S	-	38 x 44	38 x 44	10
52002846	50 x 1.5	57	39	12	41	40 - 60 S	-	45 x 51	-	5
52002847	63 x 1.5	67	43	12	46	40 - 60 S	-	49 x 56	-	5

(12.05.2024)

©2024 Lapp Group - all rights reserved.

<http://lappkorea.lappgroup.com>

data sheet

PN 0456 / 02_03.16