


SILVYN® SSVZ

SILVYN® SSVZ -

PG

가

PG

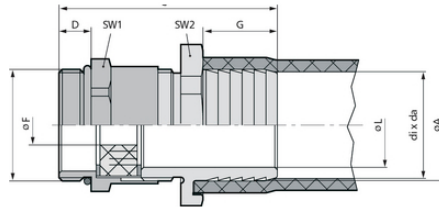

가

SILVYN® SI

SILVYN® SP

SILVYN® SP-PU

PG

SILVYN® SCH

(24.04.2024)

©2024 Lapp Group - all rights reserved.

<http://lappkorea.lappgroup.com>

data sheet

PN 0456 / 02_03.16

SILVYN® SSVZ

ETIM 5:

ETIM 5.0 Class-ID: EC001180

ETIM 5.0 Class :

ETIM 6:

ETIM 6.0 Class-ID: EC001180

ETIM 6.0 Class :

:

:

: CR/NBR

O- : NBP

:

-20°C +80°C

가 VAT 가 가 .

(24.04.2024)

©2024 Lapp Group - all rights reserved.

<http://lappkorea.lappgroup.com>

data sheet

PN 0456 / 02_03.16



SILVYN® SSVZ

	PG	SW 1/2 mm	mm	(thread) (mm)	(mm)	SILVYN® SCH	SILVYN® SI	SILVYN® SP	SILVYN® SP- PU	/ PU
SILVYN® SSVZ										
52021070	9	19.0 / 17.0	39.1	6	8	10 - 16 S	-	10 x 14	10 x 14	50
52021080	9	19.0 / 17.0	39.1	6	10	12 - 20 S	-	12 x 16	12 x 16	50
52003020	11	22.0 / 20.0	39.6	6	12	16 - 25 S	-	14 x 18	14 x 18	50
52024670	11	22.0 / 20.0	39.6	6	12	16 - 25 S	-	16 x 20	16 x 20	50
52003030	13.5	25.0 / 22.0	43.1	6.5	14	20 - 32 S	18 x 22	-	-	50
52003040	16	30.0 / 24.0	44.1	6.5	16	20 - 32 S	-	22 x 27	22 x 27	25
52003050	21	32.0 / 30.0	48.1	7	21	20 - 32 S	23 x 28	-	-	25
52003060	29	40.0 / 40.0	53.6	8	27	25 - 40 S	-	30 x 36	30 x 36	25
52024680	29	42.0 / 40.0	53.6	8	30	35 - 50 S	32 x 38	-	-	25