

## Detectable Cable ties

Matching accessories:  
Detectable cable tie sockets



**ECOLAB**



X ,

가

HACCP EU-

Polyamid version: resistant to conventional solvents such as alcohol and ketone, aliphatic and aromatic hydrocarbons such as oil, grease, gasoline and weak alkalis; not resistant to acids (weak or strong) and metallic salts

Polypropylene version: especially resistant against chemical detergents

Ty-Rap® NDT: UV resistant

( )

(24.04.2024)

©2024 Lapp Group - all rights reserved.

<http://lappkorea.lappgroup.com>

data sheet

PN 0456 / 02\_03.16

# Detectable Cable ties

Flammability class:  
UL 94 HB

ECOLAB

Storage requirements: nylon (polyamide) is, by its nature, susceptible to external influences. Cable ties are mechanically moistened in order to ensure optimal use. As such, they must be stored in a cool, dry location and must not be exposed to direct sunlight. Cable ties are packed in plastic bags to retain moisture; these should remain closed until the cable ties are used

ETIM 5:

ETIM 5.0 Class-ID: EC000046

ETIM 5.0 :

ETIM 6:

ETIM 6.0 Class-ID: EC000046

ETIM 6.0 Class :

:

6.6

:

Ty-Rap® NDT: -60°C up to +85°C

:

Ty-Rap® PDT and Detect: -40°C up to +85°C

:

Installation temperature:

-5°C up to +60°C

TY-RAP® Thomas & Betts

가 VAT 가 가 .

# Detectable Cable ties


	Article description	UL	x (mm)	Bundling Ø (mm)	(N)	/ PU
가 / PA 6.6						
61723360	Kabelbinder Detect 100x 2,5 BU	no	98.0 x 2.5	1.0 - 21.0	80.0	100
61723364	140x3.5 BU	no	140.0 x 3.5	2.0 - 32.0	180.0	100
61723365	200x3.5 BU	no	200.0 x 3.5	3.0 - 50.0	180.0	100
61723361	Kabelbinder Detect 200 x 4,5 BU	no	200 x 4.5	3.0 - 50.0	220.0	100
61723366	290x4.5 BU	no	290.0 x 4.5	3.5 - 78.0	220.0	100
61723362	Kabelbinder Detect 380 x 4,5 BU	no	360.0 x 4.5	3.5 - 100.0	220.0	100
61723363	Kabelbinder Detect 360 x 7,5 BU	no	365.0 x 7.5	8.0 - 100.0	540.0	100
(TY-RAP® ) / PA 6.6						
61723351	Cable tie TY-RAP TY523MR-NDT	no	93.0 x 2.3	1.5 - 16.0	50.0	100
61723359	Cable tie TY-RAP TY524MR-NDT	no	140.0 x 3.6	2.0 - 35.0	160.0	100
61723352	Cable tie TY-RAP TY525M-NDT	no	186.0 x 4.6	3.0 - 45.0	200.0	100
61723353	Cable tie TY-RAP TY528M-NDT	no	361.0 x 4.8	4.8 - 102.0	220	100
61723354	Cable tie TY-RAP TY527MR-NDT	no	345.0 x 6.9	4.8 - 102.0	540	100
(TY-RAP® ) /						
61723355	Cable tie TY-RAP TY523M-PDT	no	92 x 2.4	2 - 16	50	100
61723356	Cable tie TY-RAP TY525M-PDT	no	186 x 4.8	3.5 - 45	135.0	100
61723357	Cable tie TY-RAP TY528M-PDT	no	360 x 4.8	3.5 - 102	135.0	100
61723358	Cable tie TY-RAP TY527M-PDT	no	340 x 7	6 - 90	270	100

(24.04.2024)

©2024 Lapp Group - all rights reserved.  
<http://lappkorea.lappgroup.com>

data sheet  
 PN 0456 / 02\_03\_16

## Detectable Cable ties

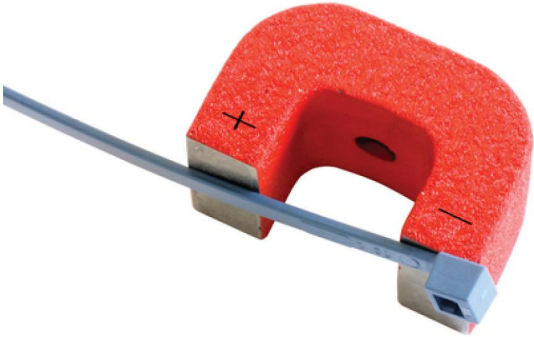

(24.04.2024)

©2024 Lapp Group - all rights reserved.

<http://lappkorea.lappgroup.com>

data sheet

PN 0456 / 02\_03.16