


EKK single clamp

EKK

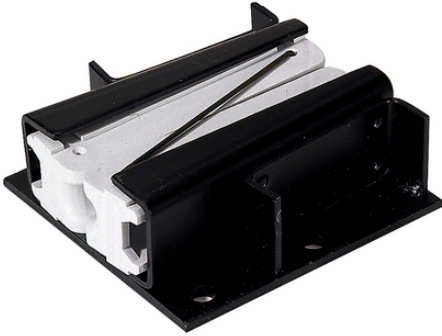

ÖLFLEX® 가 -LIFT RH RS T5
: 800 N (80 kg)

가

ETIM 5:

ETIM 5.0 Class-ID: EC000127
ETIM 5.0 :

ETIM 6:

ETIM 6.0 Class-ID: EC000127
ETIM 6.0 Class :

:

High mechanical load: +65°C
Low mechanical load: +100°C

가 VAT 가 가 .

(25.04.2024)



EKK single clamp

		Ø (mm)	x x (mm)	(kg/)	/ PU
52026000	EKK 18	15.0 - 18.0	125.0 x 45.0 x 120.0	1.4	1
52026011	EKK 26	19.0 - 26.0	125.0 x 45.0 x 120.0	1.4	1

(25.04.2024)

©2024 Lapp Group - all rights reserved.

<http://lappkorea.lappgroup.com>

data sheet

PN 0456 / 02_03.16