


AHK

3 kV

Now with UL approval

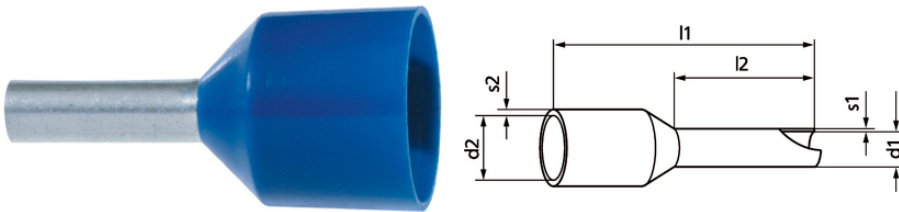

3kV short circuit -

가

Special conductor end sleeve model with large plastic collar for thick insulation cables (e.g. NSGAFÖU)

UL File Nr. E507990,

ETIM 5:	ETIM 5.0 Class-ID: EC000005
	ETIM 5.0 class :
ETIM 6:	ETIM 6.0 Class-ID: EC000005
	ETIM 6.0 Class :
:	/PP
	:
:	-5°C ~ +105°C

(25.04.2024)

AHK

가 VAT 가 가 .

(25.04.2024)

		mm ²	UL		l1 mm	l2 mm	d1 mm	s1 mm	d2 mm	s2 mm		/ PU
61746500	AHK 1,5/8	1.5	yes		17.5	8	1.8	0.15	7.5	0.3	PEW 12.090	100
61746501	AHK 1,5/10	1.5	no		19.5	10	1.8	0.15	7.5	0.3	PEW 12.090	100
61746502	AHK 2,5/8	2.5	yes		17.5	8	2.3	0.15	8	0.3	PEW 12.090	100
61746503	AHK 2,5/12	2.5	yes		21.5	12	2.3	0.15	8	0.3	PEW 12.090	100
61746504	AHK 4/10	4	yes		19.5	10	2.9	0.2	9.5	0.3	PEW 12.090	100
61746505	AHK 6/ 12	6	yes		23	12	3.6	0.2	10	0.3	PEW 12.090	100
61746506	AHK 10/12	10	yes		24	12	4.6	0.2	11.5	0.3	PEW 12.091	100
61746507	AHK 16/12	16	yes		25.5	12	6	0.2	13.5	0.3	PEW 12.091	100

(25.04.2024)

©2024 Lapp Group - all rights reserved.

<http://lappkorea.lappgroup.com>

data sheet

PN 0456 / 02_03.16