


KRFN

class 2 5

KRFN

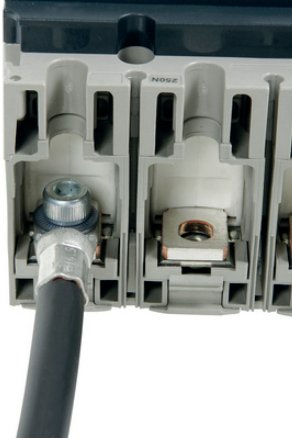

Can be installed through cable glands, allowing pre-assembly
가

50-240 mm² CU , 2 5

EN-IEC 61238:1, BS 4579:1 VDE 0220:1

ETIM 5:

ETIM 5.0 Class-ID: EC001051
ETIM 5.0 class :

:

:

+90°C
: 110°C, . +140°C

*

,

가 VAT 가 가 .

(23.04.2024)

KRFN

		Ø (mm)	UL	(mm)		d mm	W mm	/ PU
61797400	KRFN 50/6	6	no	51	B 14.5	11	18	100
61797401	KRFN 50/8	8	no	51	B 14.5	11	18	100
61797402	KRFN 50/10	10	no	51	B 14.5	11	18	100
61797403	KRFN 70/6	6	no	56	B 14.5	13	20	50
61797404	KRFN 70/8	8	no	56	B 17	13	20	50
61797405	KRFN 70/10	10	no	56	B 17	13	20	50
61797406	KRFN 95/8	8	no	61	B 20	15	24	50
61797407	KRFN 95/10	10	no	62	B 20	15	24	50
61797408	KRFN 95/12	12	no	64	B 20	15	24	50
61797409	KRFN 120/8	8	no	65	B 22	17	26	25
61797410	KRFN 120/10	10	no	66	B 22	17	26	25
61797411	KRFN 120/12	12	no	68	B 22	17	26	25
61797412	KRFN 150/10	10	no	73	B 25/13 B 25	19	30	25
61797413	KRFN 150/12	12	no	75	B 25/13 B 25	19	30	25
61797414	KRFN 185/10	10	no	80	13 B 27	21	32	20
61797415	KRFN 185/12	12	no	82	13 B 27	21	32	20
61797417	KRFN 240/10	10	no	84	13 B 30	22.5	38	10
61797418	KRFN 240/12	12	no	84	13 B 30	22.5	38	10

(23.04.2024)

©2024 Lapp Group - all rights reserved.

<http://lappkorea.lappgroup.com>

data sheet

PN 0456 / 02_03.16