


Shrink tube PROTECT-HF

Shrink Tube

Shrink Tube PROTECT-HF RW

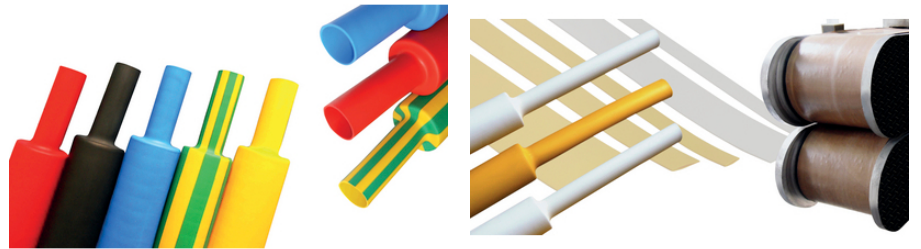

가

가

PROTECT-HF RW:

Green-yellow shrink tube: For identifying and marking earthing connectors and cables
PROTECT-HF RW:

Halogen-free
Good chemical resistance please see Appendix T1

UV ()

PROTECT-HF / Box: 가
PROTECT-HF RW: 가

FMVSS 302
ASTM D 635-HB,

(BS-6853(1999), EN 45545-2 HL 3, LUL 1-085 A3

(24.04.2024)

Shrink tube PROTECT-HF

1A), M7

Boeing BSS 7239 가

PROTECT-HF Box:
PROTECT-HF: 1.22m
PROTECT-HF RW:

ETIM 5:

ETIM 5.0 Class-ID: EC000217
ETIM 5.0 Class-Description: Schrumpfschlauch

ETIM 6:

ETIM 6.0 Class-ID: EC000217
ETIM 6.0 Class :

:

가

:

: 20 kV/mm

:

: 2:1

:

Black, Green-yellow, Yellow, White

:

:

: +90°C

PROTECT-HF / Box: -30°C ~ +105°C PROTECT-HF RW:
-55°C ~ +105°C

가 VAT

가 가 .

(24.04.2024)

Shrink tube PROTECT-HF

	Article description		(mm)	mm , +- 0.1	/ PU	PU
Shrink tube PROTECT-HF Box						
61742489	PROTECT-HF Box 1,2/0,6 BK		1.2 - 0.6	0.41	15	1
61742490	PROTECT-HF Box 1,6/0,8 BK		1.6 - 0.8	0.43	15	1
61742491	PROTECT-HF Box 2,4/1,2 BK		2.4 - 1.2	0.51	15	1
61742492	PROTECT-HF Box 3,2/1,6 BK		3.2 - 1.6	0.51	15	1
61742493	PROTECT-HF Box 4,8/2,4 BK		4.8 - 2.4	0.51	12	1
61742494	PROTECT-HF Box 6,4/3,2 BK		6.4 - 3.2	0.65	12	1
61742495	PROTECT-HF Box 9,5/4,7 BK		9.5 - 4.7	0.65	10	1
61742496	PROTECT-HF Box 12,7/6,4 BK		12.7 - 6.4	0.65	8	1
61742497	PROTECT-HF Box 19,1/9,5 BK		19.1 - 9.5	0.77	5	1
61742498	PROTECT-HF Box 25,4/12,7 BK		25.4 - 12.7	0.89	3	1
Shrink tube PROTECT-HF						
61742472	PROTECT-HF 1,2/0,6 BK		1.2 - 0.6	0.41	61	1
61742473	PROTECT-HF 1,6/0,8 BK		1.6 - 0.8	0.43	61	1
61742474	PROTECT-HF 2,4/1,2 BK		2.4 - 1.2	0.51	61	1
61742475	PROTECT-HF 3,2/1,6 BK		3.2 - 1.6	0.51	61	1
61742476	PROTECT-HF 4,8/2,4 BK		4.8 - 2.4	0.51	61	1
61742477	PROTECT-HF 6,4/3,2 BK		6.4 - 3.2	0.65	30.5	1
61742478	PROTECT-HF 9,5/4,7 BK		9.5 - 4.7	0.65	30.5	1
61742479	PROTECT-HF 12,7/6,4 BK		12.7 - 6.4	0.65	30.5	1
61742480	PROTECT-HF 19,1/9,5 BK		19.1 - 9.5	0.77	30.5	1

(24.04.2024)

©2024 Lapp Group - all rights reserved.

<http://lappkorea.lappgroup.com>

data sheet

PN 0456 / 02_03.16

Shrink tube PROTECT-HF

	Article description		(mm)	mm , +- 0.1	/ PU	PU
61742481	PROTECT-HF 25,4/12,7 BK		25.4 - 12.7	0.89	18.3	1
61742482	PROTECT-HF 3,2/1,6 GN/YE	-	3.2 - 1.6	0.51	61	1
61742483	PROTECT-HF 4,8/2,4 GN/YE	-	4.8 - 2.4	0.51	61	1
61742484	PROTECT-HF 6,4/3,2 GN/YE	-	6.4 - 3.2	0.65	30.5	1
61742485	PROTECT-HF 9,5/4,7 GN/YE	-	9.5 - 9.5	0.65	30.5	1
61742486	PROTECT-HF 12,7/6,4 GN/YE	-	12.7 - 6.4	0.65	30.5	1
61742487	PROTECT-HF 19,1/9,5 GN/YE	-	19.1 - 9.5	0.77	30.5	1
61742488	PROTECT-HF 25,4/12,7 GN/YE	-	25.4 - 12.7	0.89	18.3	1
Shrink tube PROTECT-HF RW						
61742499	PROTECT-HF RW 2,4/1,2 BK		2.4 - 1.2	0.43 - 0.6	300	1
61742501	PROTECT-HF RW 3,2/1,6 BK		3.2 - 1.6	0.55 - 0.72	300	1
61742502	PROTECT-HF RW 4,8/2,4 BK		4.8 - 2.4	0.55 - 0.72	300	1
61742503	PROTECT-HF RW 6,4/3,2 BK		6.4 - 3.2	0.65 - 0.8	300	1
61742504	PROTECT-HF RW 9,5/4,7 BK		9.5 - 4.7	0.65 - 0.75	150	1
61742505	PROTECT-HF RW 12,7/6,4 BK		12.7 - 6.4	0.65 - 0.75	100	1
61742506	PROTECT-HF RW 19,1/9,5 BK		19.1 - 9.5	0.7 - 0.85	50	1
61742507	PROTECT-HF RW 25,4/12,7 BK		25.4 - 12.7	0.85 - 1.0	50	1
61742508	PROTECT-HF RW 2,4/1,2 WH		2.4 - 1.2	0.43 - 0.6	300	1
61742509	PROTECT-HF RW 3,2/1,6 WH		3.2 - 1.6	0.55 - 0.72	300	1
61742510	PROTECT-HF RW 4,8/2,4 WH		4.8 - 2.4	0.55 - 0.72	300	1
61742511	PROTECT-HF RW		6.4 - 3.2	0.65 - 0.8	300	1

(24.04.2024)

©2024 Lapp Group - all rights reserved.

<http://lappkorea.lappgroup.com>

data sheet

PN 0456 / 02_03.16

Shrink tube PROTECT-HF

	Article description	(mm)	, +- 0.1 mm	/ PU	PU
	6,4/3,2 WH				
61742512	PROTECT-HF RW 9,5/4,7 WH	9.5 - 4.7	0.65 - 0.75	150	1
61742513	PROTECT-HF RW 12,7/6,4 WH	12.7 - 6.4	0.65 - 0.75	100	1
61742514	PROTECT-HF RW 19,1/9,5 WH	19.1 - 9.5	0.7 - 0.85	50	1
61742523	PROTECT-HF RW 25,4/12,7 WH	25.4 - 12.7	0.85 - 1.0	50	1
61742515	PROTECT-HF RW 2,4/1,2 YE	2.4 - 1.2	0.43 - 0.6	300	1
61742516	PROTECT-HF RW 3,2/1,6 YE	3.2 - 1.6	0.55 - 0.72	300	1
61742517	PROTECT-HF RW 4,8/2,4 YE	4.8 - 2.4	0.55 - 0.72	300	1
61742518	PROTECT-HF RW 6,4/3,2 YE	6.4 - 3.2	0.65 - 0.8	300	1
61742519	PROTECT-HF RW 9,5/4,7 YE	9.5 - 4.7	0.65 - 0.75	150	1
61742520	PROTECT-HF RW 12,7/6,4 YE	12.7 - 6.4	0.65 - 0.75	100	1
61742521	PROTECT-HF RW 19,1/9,5 YE	19.1 - 9.5	0.7 - 0.85	50	1
61742522	PROTECT-HF RW 25,4/12,7 YE	25.4 - 12.7	0.85 - 1.0	50	1

(24.04.2024)

©2024 Lapp Group - all rights reserved.

<http://lappkorea.lappgroup.com>

data sheet

PN 0456 / 02_03.16