


TEC

TEC

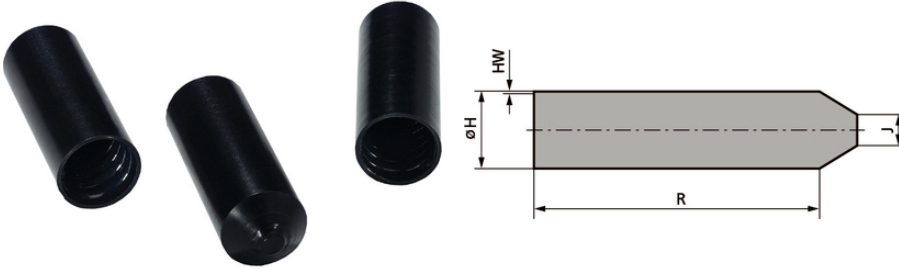

가

가

ETIM 5:

ETIM 5.0 Class-ID: EC000218

ETIM 5.0 Class-Description: Schrumpf-Endkappe

ETIM 6:

ETIM 6.0 Class-ID: EC000218

ETIM 6.0 Class :

:

UV-

:

:

가

가

:

-55°C~+100 °C

: 135°C

(24.04.2024)

©2024 Lapp Group - all rights reserved.

<http://lappkorea.lappgroup.com>

data sheet

PN 0456 / 02_03.16

TEC

1. +/- 10%; 2. +/- 20%

가 VAT 가 가 .

	Article description	H max. (mm)	H min. (mm)	J max. (mm)	Cable Ø (mm)	R* after (mm)	HW* (mm)	/ PU
61830000	TEC 15/4,5	15	4.5	4	5 - 12	30	2	10
61830010	TEC 25/9	25	9	6.5	10 - 22	50	2.3	10
61830020	TEC 36/15	36	15	10.5	17 - 30	80	3	10
61830040	TEC 55/25	55	25	16	28 - 47	130	3.3	10
61830050	TEC 80/40	80	40	17	45 - 70	150	4	10
61830060	TEC 102/60	102	60	26	68 - 90	140	4	10
61830070	TEC 148/57	148	57	27	80 - 133	105	3.3	10

(24.04.2024)

©2024 Lapp Group - all rights reserved.

<http://lappkorea.lappgroup.com>

data sheet

PN 0456 / 02_03.16