


3M Scotch™ 1183

3M Scotch™ 1183

UL

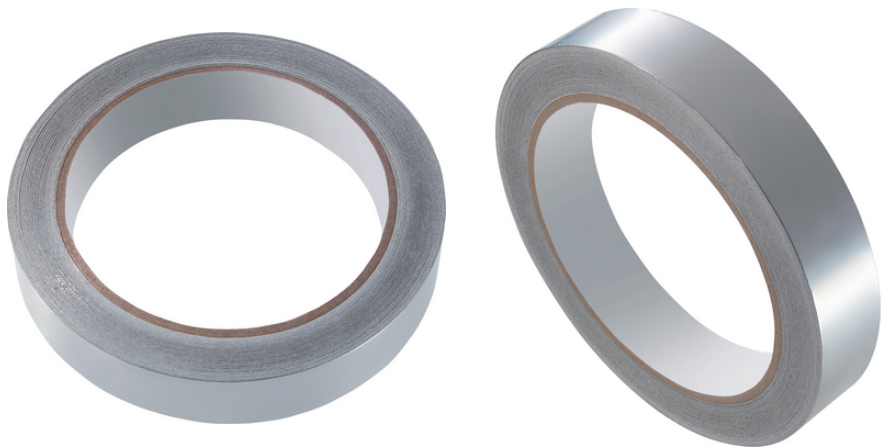

가

가

UL 510

UL : E17385

ETIM 5:

ETIM 6:

ETIM 5.0 Class-ID: EC000128

ETIM 5.0 :

ETIM 6.0 Class-ID: EC000128

ETIM 6.0 Class :

(24.04.2024)

©2024 Lapp Group - all rights reserved.

<http://lappkorea.lappgroup.com>

data sheet

PN 0456 / 02_03.16

3M Scotch™ 1183

：	() : 3.8 N/10 mm
：	: 44 N/10 mm
：	Contact resistance (in acc. with MIL-STD-202): 0.005 Ω
：	： 50%) (
：	(: RAL 7001)
：	
：	-10 °C +80 °C

Scotch™ 1183 3M .

가 VAT 가 가 .

(24.04.2024)

©2024 Lapp Group - all rights reserved.

<http://lappkorea.lappgroup.com>

data sheet

PN 0456 / 02_03.16



3M Scotch™ 1183

		(mm)	PU (m)
61721420	3M Scotch 1183 / 9x16,5	9	16.5
61721421	3M Scotch 1183 / 12x16,5	12	16.5
61721422	3M Scotch 1183 / 19x16,5	19	16.5
61721423	3M Scotch 1183 / 25x16,5	25	16.5

(24.04.2024)

©2024 Lapp Group - all rights reserved.

<http://lappkorea.lappgroup.com>

data sheet

PN 0456 / 02_03.16